


## Discover these time-saving products at Graybar!

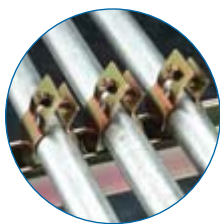

### **Kindorf® Angler™** *Pipe and Conduit Clamp*

Bent-tab design allows the bolt to extend up at a 30° angle for easy access even when clamps are side by side. One-piece design saves handling time. No need to unscrew the bolt before installing.




### **Steel City®** *EMT Raintight Fittings*

Easily identified by its trademark gold-colored gland nut, our UL-listed EMT raintight compression fitting is designed for easy inspection, even from a distance.




### **Superstrut® Cobra™** *Cable and Pipe Clamp*

Ready to install with one hand, right out of the box! No need to break apart and reassemble, no screws or bolts to drop, and no need to disturb nearby clamps when reconfiguring cables. Available in SilverGalv® finish.

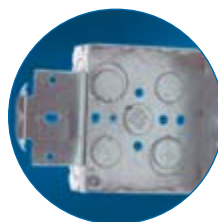

### **Steel City®** *MS Type Mounting Bracket*

The fastest installing metal stud box mount in the industry. Just pop right onto a stud in the required location — without tools or screws to slow down the installation.

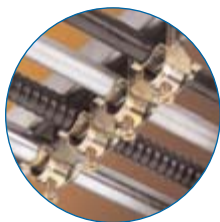

### **Kindorf® King Cobra™** *Cable and Pipe Clamp*

Ready to install with one hand, right out of the box! No need to break apart and reassemble, no screws or bolts to drop, and no need to disturb nearby clamps when reconfiguring cables. Available in GoldGalv® finish.




### **Steel City® GO Box**

Designed for residential projects, this single gang plastic box clamps onto a wood stud without tools or fasteners — just push the box onto the stud and call the job done.



### **Steel City®** *Hands-Free Swivel Hanger*

Reduce installation time! Install high- and low-bay lighting fixtures faster with a single installer. Fixtures can be set in place before wiring is completed. Conductors can be reached after mounting fixtures.

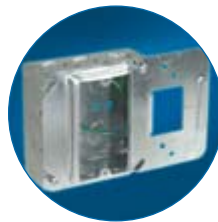

### **Steel City®** *Pre-Fabricated Box and Cover Assemblies*

Speed up your rough-in installation with time-saving pre-fabricated assemblies for more profitable work. 48 combinations of boxes, brackets and covers.



### **Steel City®** *4" Square Old Work Box with Swing Ears*

Make your old work or retrofit installations faster and more secure — these 4" square boxes feature pre-mounted swing ears for quick installs on existing drywall up to 3/4-inch thick. The OW swing ear also is sold separately.

# Time-saving products from Thomas & Betts.

## Kindorf® Angler™ Pipe and Conduit Clamp

### Universal Series

Galvkrom® Finish

C 109 1/2  
C 109 3/4  
C 109 1  
C 109 1 1/4  
C 109 1 1/2  
C 109 2  
C 109 2 1/2  
C 109 3  
C 109 3 1/2  
C 109 4

ElectroGalv® Finish

C 109 1/2 EG  
C 109 3/4 EG  
C 109 1 EG  
C 109 1 1/4 EG  
C 109 1 1/2 EG  
C 109 2 EG  
C 109 2 1/2 EG  
C 109 3 EG  
C 109 3 1/2 EG  
C 109 4 EG

### Rigid Series

Galvkrom® Finish

C 109R 1/2  
C 109R 3/4  
C 109R 1  
C 109R 1 1/4  
C 109R 1 1/2  
C 109R 2  
C 109 2 1/2  
C 109 3  
C 109 3 1/2  
C 109 4

ElectroGalv® Finish

C 109R 1/2 EG  
C 109R 3/4 EG  
C 109R 1 EG  
C 109R 1 1/4 EG  
C 109R 1 1/2 EG  
C 109R 2 EG  
C 109 2 1/2 EG  
C 109 3 EG  
C 109 3 1/2 EG  
C 109 4 EG

## Superstrut® Cobra™ One-Piece Cable and Pipe Clamp

Electro Galvanized Steel

CPC050  
CPC075  
CPC100  
CPC125  
CPC150  
CPC200  
CPC250  
CPC300  
CPC350  
CPC400

316 Stainless Steel

CPC050SS6  
CPC075SS6  
CPC100SS6  
CPC125SS6  
CPC150SS6  
CPC200SS6  
CPC250SS6  
CPC300SS6  
CPC350SS6  
CPC400SS6

## Kindorf® King Cobra™ Cable and Pipe Clamp with GoldGalv® Finish

GoldGalv® Finish

KCPC050  
KCPC075  
KCPC100  
KCPC125  
KCPC150  
KCPC200  
KCPC250  
KCPC300  
KCPC350  
KCPC400

316 Stainless Steel

KCPC050SS6  
KCPC075SS6  
KCPC100SS6  
KCPC125SS6  
KCPC150SS6  
KCPC200SS6  
KCPC250SS6  
KCPC300SS6  
KCPC350SS6  
KCPC400SS6

## Steel City® Hands-Free Swivel Hanger

SHHF1234  
SHHFR1234

## Steel City® 4" Square Old Work Box with Swing Ears

52171 OW  
OW SWING EAR

## Steel City® EMT Raintight Fittings

TC111A-RT  
TC112A-RT  
TC113A-RT  
TC114A-RT  
TC115A-RT  
TC116A-RT

TK111A-RT  
TK112A-RT  
TK113A-RT  
TK114A-RT  
TK115A-RT  
TK116A-RT

## Steel City® MS Type Mounting Bracket

52151 MS 1/2 3/4  
52151 MS N  
52151 MS X  
52171 MS 1/2 3/4  
52171 MSN  
52171 MSX  
72171 MS 1/2 3/4

## Steel City® GO Box

GO-23  
GO-23-FS

## Steel City® Pre-Fabricated Box and Cover Assemblies

52CM13  
52CM14-5/8  
52CM14  
52CMD17  
52CMD18-5/8  
52CMD18  
52151-CM13  
52151-CM1458  
52151-CM14  
52151-CMD17  
52151-CMD1858  
52151-CMD18  
52171-CM13  
52171-CM1458  
52171-CM14  
52171-CMD17  
52171-CMD1858  
52171-CMD18  
52171-CM13

52171-CM1458  
52171-CM14  
52171-CMD17  
52171-CMD1858  
52171-CMD18  
151-SH2346-13  
151-SH2346-1458  
151-SH2346-14  
151-SH2346-17  
151-SH2346-1858  
151-SH2346-18  
171-SH2346-13  
171-SH2346-1458  
171-SH2346-14  
171-SH2346-17  
171-SH2346-1858  
171-SH2346-18  
151-SV12-13  
151-SV12-1458  
151-SV12-14  
151-SV12-17  
151-SV12-1858  
151-SV12-18  
171-SV12-13  
171-SV12-1458  
171-SV12-14  
171-SV12-17  
171-SV12-1858  
171-SV12-18  
151-SV18-13  
151-SV18-1458  
151-SV18-14  
151-SV18-17  
151-SV18-1858  
151-SV18-18  
171-SV18-13  
171-SV18-1458  
171-SV18-14  
171-SV18-17  
171-SV18-1858  
171-SV18-18

52151-1/2&3/4-EWP  
52151-1/2&3/4-P  
52171-1/2&3/4-1/2&3.EP

52151-XP  
52151-CVNP  
LXWOWP  
LXVP  
CXWOWP  
CXWVP  
CXP  
SSF-SH2346  
SSF-SH4  
SSF-SH6  
SSF-SG1 16  
SSF-SG1 24  
SSF-SG16P  
SSF-SG16A  
SSF-SG216  
SSF-SG2 24  
SSF-SG24P  
SSF-SG24A  
SSF-SB16  
SSF-SB24  
SSF-SB16F  
SSF-SB24F  
SSF-SV12  
SSF-SV18  
SSF-S6X  
SV1218  
SVX  
SBO16  
SBO24