
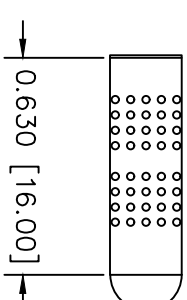
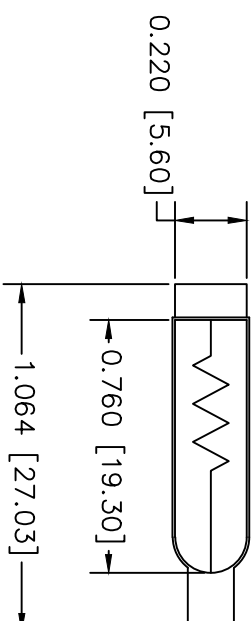
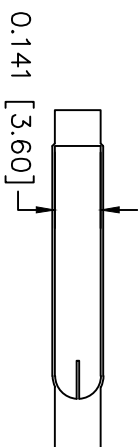
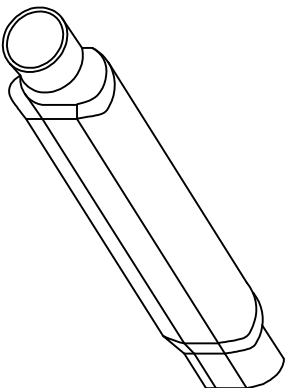


NOTES:

1. ACCEPTS 16-24 GAUGE WIRES
2. MOISTURE RESISTANT BARRIER (FILLED)
3. NON-CURING SEALANT (FILLED)
4. WILL NOT LEAK OUT WHEN CRIMPED (FILLED)
5. WILL NOT CORRODE
6. WITHSTANDS TEMPERATURE RANGE OF -60°F TO 450°F
7. DIMENSIONS IN INCHES [MM]

WIRE CAPACITY:

- 4-WIRES: #24 AWG, #22 AWG (INSULATED)
- 3-WIRES: #20 AWG, #18 AWG (INSULATED)
- #16 AWG (STRIPPED)

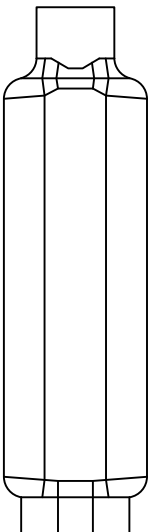

Allen Tel Products, Inc.
30 TV5 DRIVE HENDERSON, NV 89014

SUPER B WIRE CONNECTOR
GBCONN-P100 / GBCONN-S100
(UNFILLED WHITE) (FILLED BLUE)