


**NOTE:**  
DIMENSIONS IN INCHES [mm]

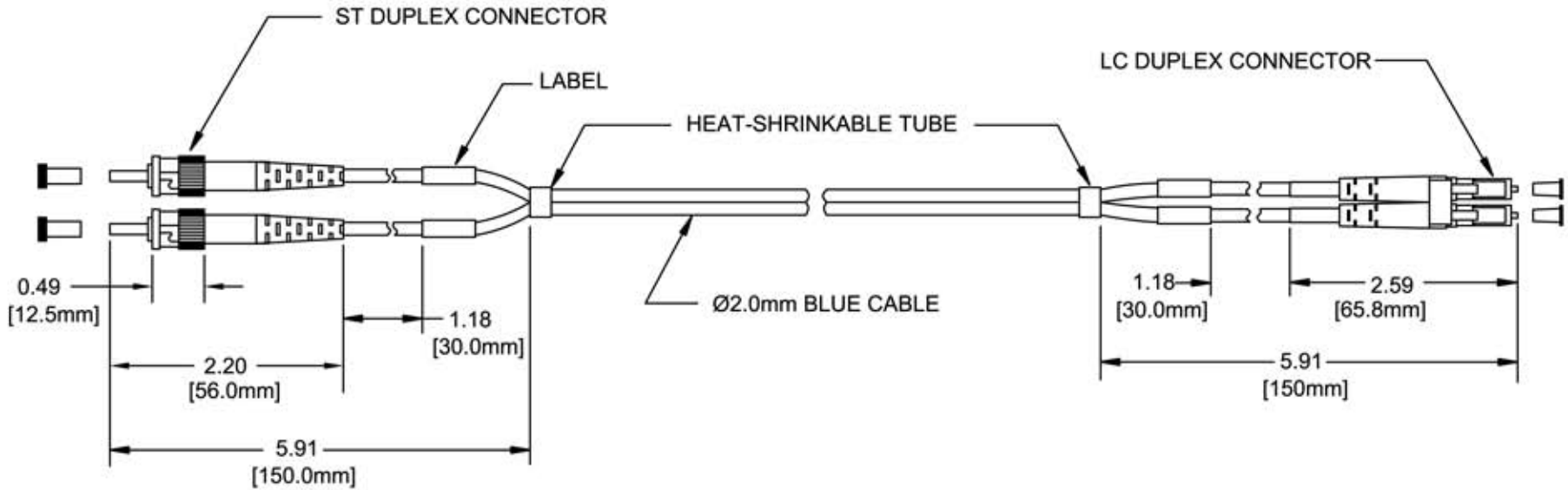

## SPECIFICATIONS

| PARAMETER              | UNITS |         |
|------------------------|-------|---------|
| FERRULE ID             | um    | 127     |
| INSERTION LOSS         | dB    | <0.3    |
| DURABILITY (500 TIMES) | dB    | <0.3    |
| OPERATING TEMPERATURE  | °C    | -40~+85 |
| STORAGE TEMPERATURE    | °C    | -40~+85 |
| TYPICAL CABLE OD       | mm    | Ø2.0    |

## FEATURES

- \* ST CONNECTORS ARE COMPLIANT IEC 60874-10; TIA/EIA-604-2
- \* LC CONNECTORS ARE COMPLIANT TIA/EIA-640-10; LUCENT: 640-252-256
- \* PRODUCT QUALITY COMPLY WITH GR-326-CORE

PART#: GBLCT-D3-**XX**

### LENGTH (METERS)

01, 02, 03, 04, 05, 06, 07,  
08, 09, 10, 15, 20, 25, 30



**Allen Tel Products, Inc.**

30 TV5 DRIVE • HENDERSON, NV • 89014

**GBLCT-D3-XX LC TO ST DUPLEX  
MULTIMODE 50/125 (BLUE JACKET)**