


NOTE:
DIMENSIONS IN INCHES [mm]

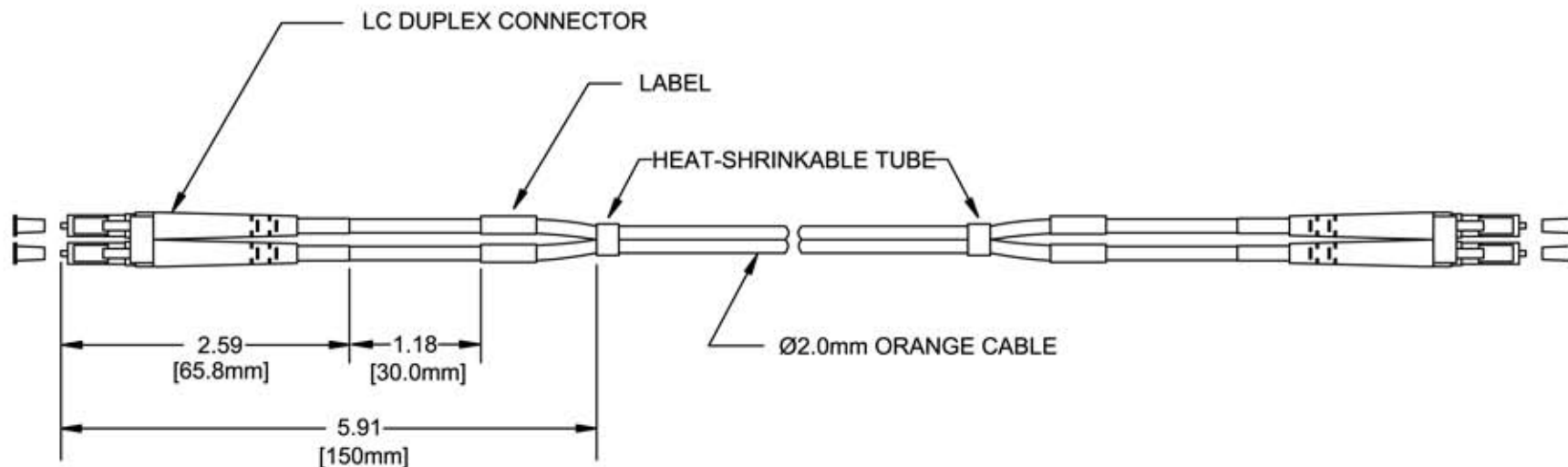

SPECIFICATIONS

PARAMETER	UNITS	
FERRULE ID	um	127
INSERTION LOSS	dB	<0.3
DURABILITY (500 TIMES)	dB	<0.3
OPERATING TEMPERATURE	°C	-40~+85
STORAGE TEMPERATURE	°C	-40~+85
TYPICAL CABLE OD	mm	Ø2.0

FEATURES

- * LC CONNECTORS ARE COMPLIANT TIA/EIA-640-10; LUCENT: 640-252-256
- * PRODUCT QUALITY COMPLY WITH GR-326-CORE

PART#: GBLC2-D2-XX

LENGTH (METERS)

01, 02, 03, 04, 05, 06, 07,
08, 09, 10, 15, 20, 25, 30



Allen Tel Products, Inc.
30 TV5 DRIVE • HENDERSON, NV • 89014

**GBLC2-D2-XX LC TO LC DUPLEX
MULTIMODE 62.5/125 (ORANGE JACKET)**

