


NOTE:
DIMENSIONS IN INCHES [mm]

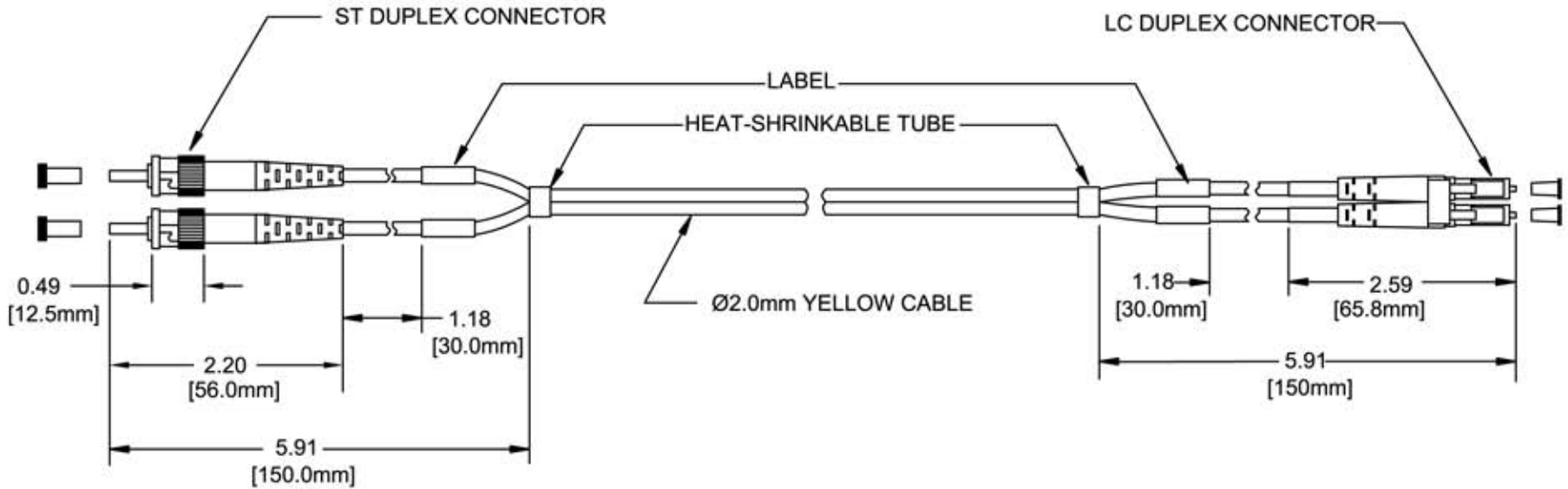

SPECIFICATIONS

PARAMETER	UNITS	
FERRULE ID	um	125
INSERTION LOSS	dB	<0.2
RETURN LOSS	dB	>50
DURABILITY (500 TIMES)	dB	<0.3
OPERATING TEMPERATURE	°C	-40~+85
STORAGE TEMPERATURE	°C	-40~+85
TYPICAL CABLE OD	mm	Ø2.0

FEATURES

- * ST CONNECTORS ARE COMPLIANT IEC 60874-10; TIA/EIA-604-2A
- * LC CONNECTORS ARE COMPLIANT TIA/EIA-640-10; LUCENT: 640-252-256
- * PRODUCT QUALITY COMPLY WITH GR-326-CORE

PART#: GBLCT-D1-XX

LENGTH (METERS)

01, 02, 03, 04, 05, 06, 07,
08, 09, 10, 15, 20, 25, 30



Allen Tel Products, Inc.

30 TV5 DRIVE • HENDERSON, NV • 89014

**GBLCT-D1-XX LC TO ST DUPLEX
SINGLEMODE 9/125 (YELLOW JACKET)**

