


**NOTE:**  
DIMENSIONS IN INCHES [mm]

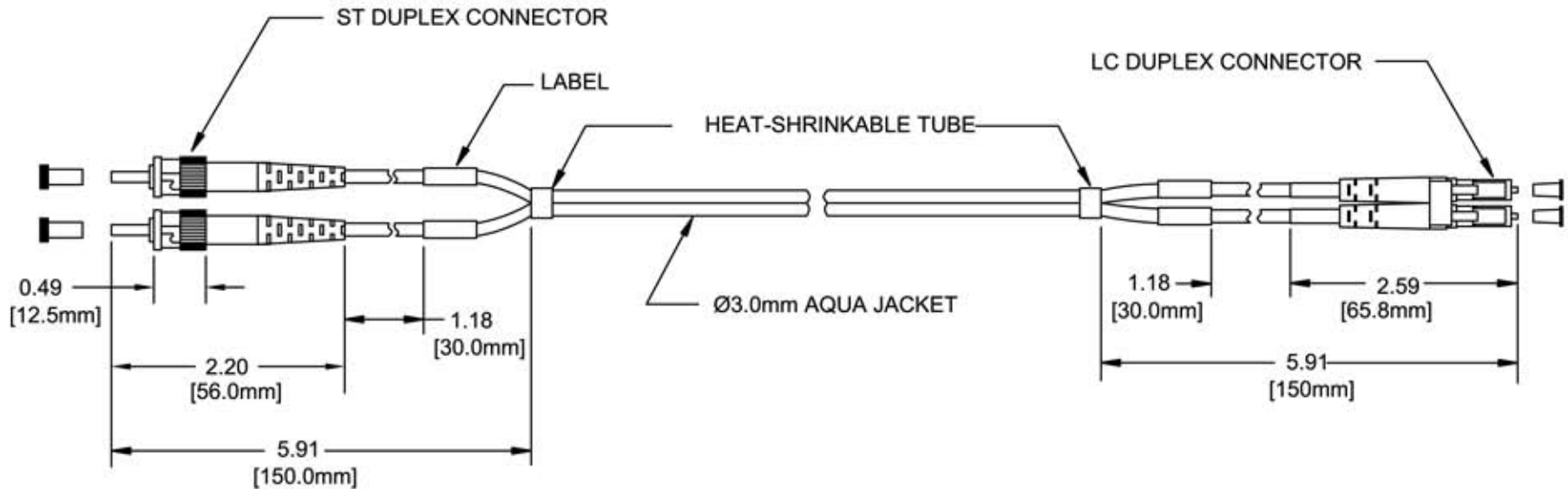

## SPECIFICATIONS

PARAMETER	UNITS	
FERRULE ID	um	127
INSERTION LOSS	dB	<0.3
DURABILITY (500 TIMES)	dB	<0.3
OPERATING TEMPERATURE	°C	-40~+85
STORAGE TEMPERATURE	°C	-40~+85
TYPICAL CABLE OD	mm	Ø3.0

## FEATURES

- \* ST CONNECTORS ARE COMPLIANT IEC 60874-10; F04 (JIS C5973); TIA/EIA-604-2A
- \* LC CONNECTORS ARE COMPLIANT TIA/EIA-640-10; LUCENT: 640-252-256
- \* PRODUCT QUALITY COMPLY WITH GR-326-CORE

PART#: GBLCT-D4-

LENGTH (METERS)

01, 02, 03, 04, 05, 06, 07,  
08, 09, 10, 15, 20, 25, 30



**Allen Tel Products, Inc.**

30 TV5 DRIVE • HENDERSON, NV • 89014

**GBLCT-D4-XX 10Gb LC TO ST DUPLEX  
MULTIMODE 50/125 OM3 (AQUA JACKET)**

