


**NOTE:**  
DIMENSIONS IN INCHES [mm]

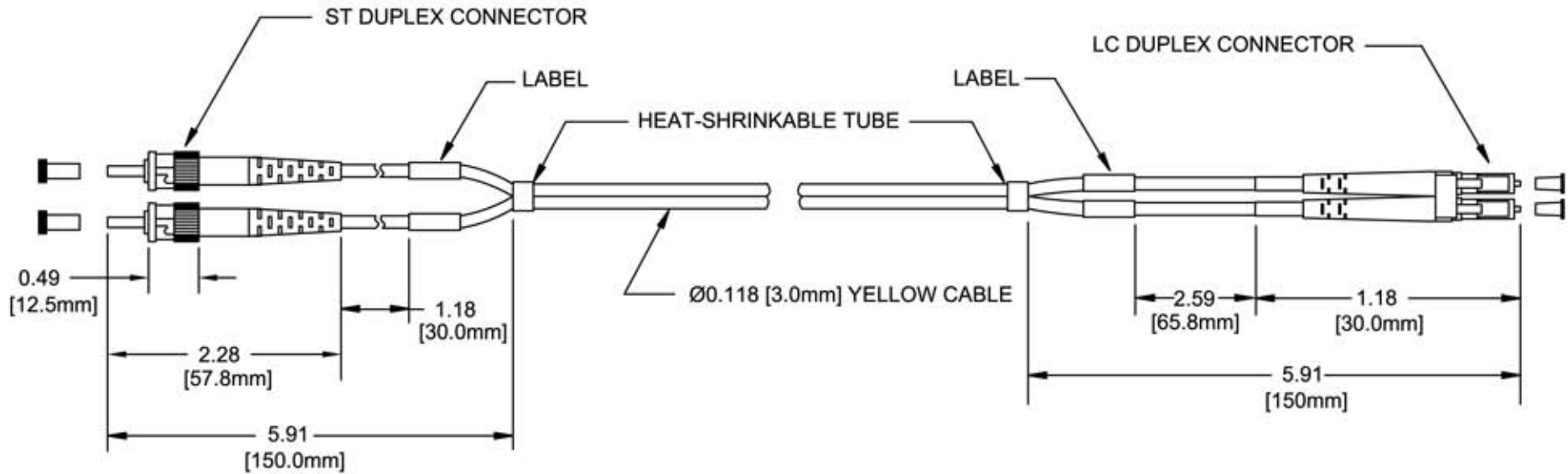

## SPECIFICATIONS

PARAMETER	UNITS	
FERRULE ID	um	125
INSERTION LOSS	dB	<0.2
RETURN LOSS	dB	>50
DURABILITY (500 TIMES)	dB	<0.3
OPERATING TEMPERATURE	°C	-40~+85
STORAGE TEMPERATURE	°C	-40~+85
TYPICAL CABLE OD	mm	Ø3.0

## FEATURES

- \* ST CONNECTORS ARE COMPLIANT IEC 60874-10; F04 (JIS C5973); TIA/EIA-604-3A
- \* SC CONNECTORS ARE COMPLIANT IEC 60874-14; F04 (JIS C5973); TIA/EIA-604-3A
- \* PRODUCT QUALITY COMPLY WITH GR-326-CORE

PART#: GBLCT-S1-XX

### LENGTH (METERS)

01, 02, 03, 04, 05, 06, 07,  
08, 09, 10, 15, 20, 25, 30



Allen Tel Products, Inc.  
30 TV5 DRIVE • HENDERSON, NV • 89014

**GBLCT-S1-XX ST TO LC SIMPLEX  
SINGLEMODE 9/125 (YELLOW JACKET)**