


**NOTE:**  
DIMENSIONS IN INCHES [mm]

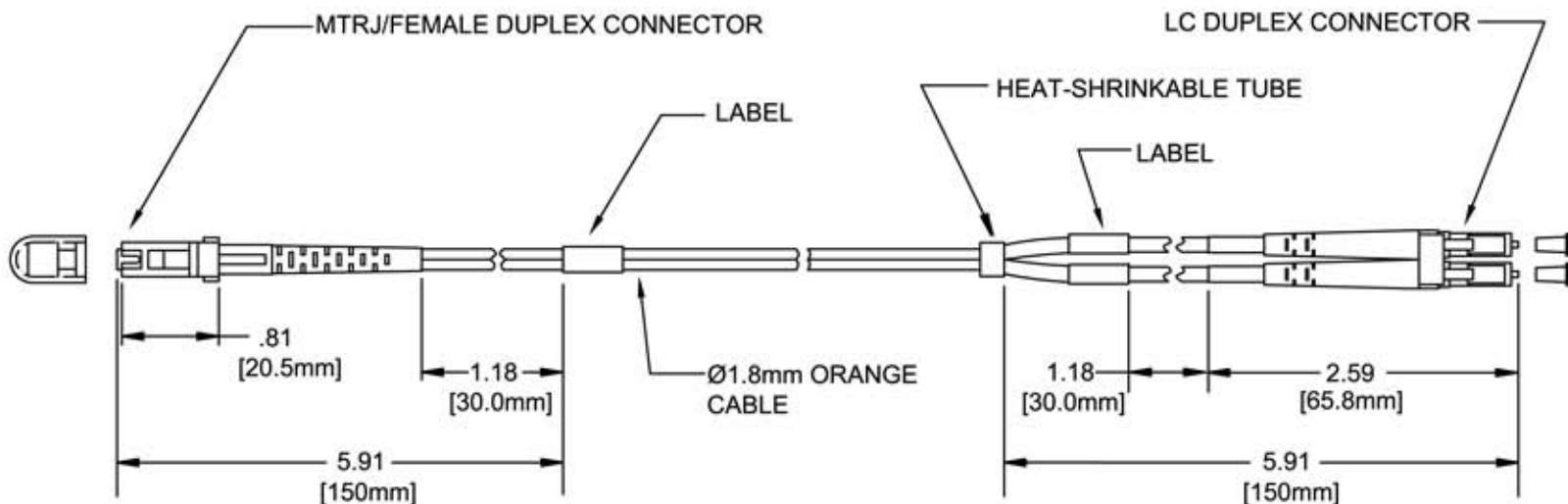

## SPECIFICATIONS

PARAMETER	UNITS	
INSERTION LOSS	dB	(<0.5 for MTRJ)
DURABILITY (500 TIMES)	dB	(<0.5 for MTRJ)
OPERATING TEMPERATURE	°C	-40~+85
STORAGE TEMPERATURE	°C	-40~+85
TYPICAL CABLE OD	mm	Ø1.8

## FEATURES

- \* MTRJ-D2 CONNECTORS ARE COMPLIANT IEC-60874-16 F12 (JIS C5981); TIA/EIA-604-12
- \* LC CONNECTORS ARE COMPLIANT TIA/EIA-640-10; LUCENT: 640-252-256
- \* PRODUCT QUALITY COMPLY WITH GR-326-CORE

PART#: GBMFL-D2-XX

LENGTH (METERS)

01, 02, 03, 04, 05, 06, 07,  
08, 09, 10, 15, 20, 25, 30



**Allen Tel Products, Inc.**  
30 TV5 DRIVE • HENDERSON, NV • 89014

**GBMFL-D2-XX MTRJ/FEMALE TO LC DUPLEX  
MULTIMODE 62.5/125 (ORANGE JACKET)**

